


Ty-Fast®kablo bağı

The TY - FAST® cable tie made of PA 6.6 is the standard cable tie for many applications. It is fulfilling several approvals.

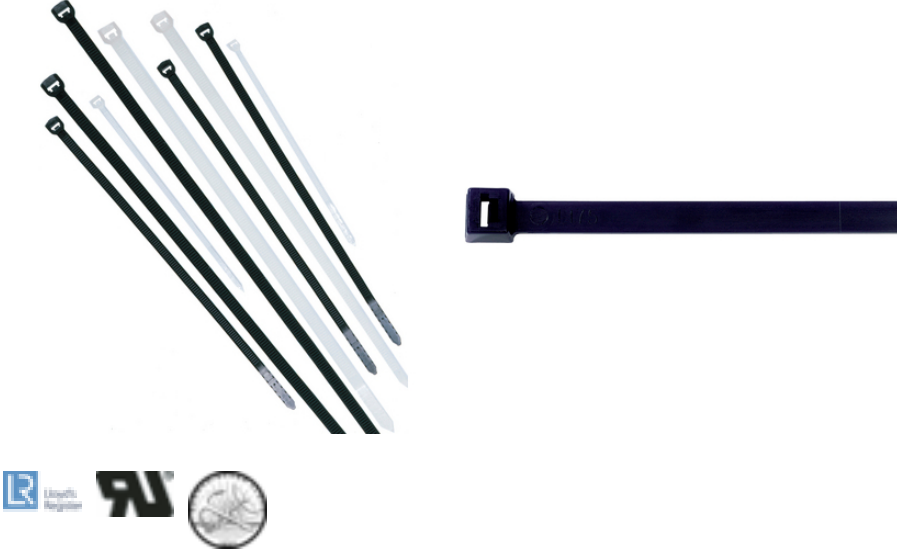

Halojen içermeyen



UV-dayanım

Faydalar

The integrally formed polyamide pawl combines low insertion and high locking strength. Sure grip tab keeps the tail from popping out while being threaded, then holds it securely for final tightening by hand or tool.

Uygulama alanı

Birçok uygulama için çok amaçlı kablo bağı

Norm referansları / Onaylar

Dosya numarası: E49405, tabloya bakın
UL94 V-2 uyarınca yangın tutumu

Teknik Veri

Sınıflandırma ETIM 5:

ETIM 5.0 Class-ID: EC000046

ETIM 5.0 Class-Tanım: Kablo bağı

Sınıflandırma ETIM 6:

ETIM 6.0 sınıf ID'si: EC000046

ETIM 6.0 sınıf açıklaması: Kablo bağı

Malzeme:

Polyamid 6.6

Halojen içermeyen ve silikon içermeyen

Sıcaklık aralığı:

-40 °C ila +85 °C

Uyarı

Son durum (29.04.2024)

©2024 Lapp Group - all rights reserved.

Ürün Yönetimi <http://lappkablo.lappgroup.com>

Karşılık gelen veri sayfasında, mevcut teknik verileri bulabilirsiniz.

PN 0456 / 02_03.16

Ty-Fast®kablo bağı

TY-FAST® ABB nin tescilli ticari markasıdır.

Fotoğraflar ve grafikler ölçekli değildir ve ilgili ürünlerin ayrıntılı görüntülerini temsil etmemektedir.

Buradaki fiyatlar, ekler ve KDV hariç net fiyatlardır. Satış sadece firma sahibi müşterilere.

Ty-Fast®kablo bağı

Ürün kodu	Ürün açıklaması	UL sertifikalandırma	Uzunluk x Genişlik (mm)	Demet Ø (mm)	Gerilme mukavemeti (N)	Adet / Paket
Doğal						
61810350	TY100-18	evet	112.0 x 2.4	25	80	1000
61810360	TY125-18	evet	136.0 x 2.4	32	80	1000
61810380	TY125-40	evet	141.0 x 3.6	32	180	1000
61810390	TY200-40	evet	205.0 x 3.6	50	180	1000
61810400	TY300-40	evet	290.0 x 3.6	76	180	1000
61810410	TY175-50	evet	186.0 x 4.6	44	220	1000
61810420	TY300-50	evet	291.0 x 4.6	76	220	1000
61810430	TY400-50	evet	366.0 x 4.6	102	220	1000
61810440	TY200-120	evet	219.0 x 7.6	50	540	500
61810450	TY400-120	evet	375.0 x 7.6	102	540	500
Siyah (UV ışınlarına karşı dayanıklı)						
61810460	TY100-18x	evet	112.0 x 2.4	25	80	1000
61810470	TY125-18x	evet	136.0 x 2.4	32	80	1000
61810490	TY125-40x	evet	141.0 x 3.6	32	180	1000
61810500	TY200-40x	evet	205.0 x 3.6	50	180	1000
61810510	TY300-40x	evet	290.0 x 3.6	76	180	1000
61810520	TY175-50x	evet	186.0 x 4.6	44	220	1000
61810530	TY300-50x	evet	291.0 x 4.6	76	220	1000
61810540	TY400-50x	evet	366.0 x 4.6	102	220	1000
61810550	TY200-120x	evet	219.0 x 7.6	50	540	500
61810560	TY400-120x	evet	375.0 x 7.6	102	540	500